 



Regulator plate

VMPA14-B8-R2C2-C-10

Part number: 8043340

FESTO

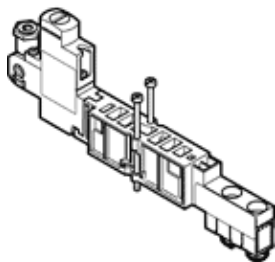

Data sheet

| Feature | Value |
|---|---|
| Width | 14 mm |
| Assembly position | Any |
| Pneumatic vertical stacking | Pressure regulator for 2 |
| Controller function | Output pressure constant with secondary exhaust |
| Pressure gauge selection | possible |
| Pressure regulation range | 2 ... 6 bar |
| Inlet pressure 1 | 0.5 ... 10 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:4:4] |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Protection class | IP65 to IEC 60529 |
| Ambient temperature | -5 ... 50 °C |
| Max. tightening torque | 0.65 Nm |
| Product weight | 76 g |
| Vertical stacking type of mounting | on manifold block |
| Pressure gauge connection | M5 |
| Materials note | Conforms to RoHS |
| Material control panel | PA |
| Material seals | NBR |
| Material regulator housing | PA |