 



# Regulator plate

## VMPA14-B8-R3C2-C-06

Part number: 8043344

FESTO

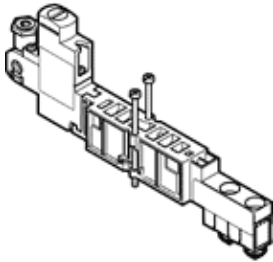

## Data sheet

| Feature                                 | Value   |
|---|---|
| Width                                   | 14 mm   |
| Assembly position                       | Any   |
| Pneumatic vertical stacking             | Pressure regulator for 4  |
| Controller function                     | Output pressure constant with secondary exhaust                             |
| Pressure gauge selection                | possible  |
| Pressure regulation range               | 2 ... 6 bar   |
| Inlet pressure 1                        | 0.5 ... 10 bar  |
| Operating medium                        | Compressed air in accordance with ISO8573-1:2010 [7:4:4]                    |
| Note on operating and pilot medium      | Lubricated operation possible (subsequently required for further operation) |
| Corrosion resistance classification CRC | 1 - Low corrosion stress  |
| PWIS conformity                         | VDMA24364-B1/B2-L   |
| Protection class                        | IP65<br>to IEC 60529  |
| Ambient temperature                     | -5 ... 50 °C  |
| Max. tightening torque                  | 0.65 Nm   |
| Product weight                          | 76 g  |
| Vertical stacking type of mounting      | on manifold block   |
| Pressure gauge connection               | M5  |
| Materials note                          | Conforms to RoHS  |
| Material control panel                  | PA  |
| Material seals                          | NBR   |
| Material regulator housing              | PA  |