


# Subbase VMPA14-FB-AP-4-1-T1

Part number: 8043928

FESTO

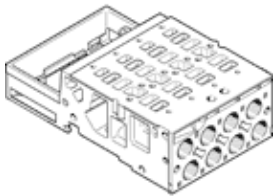

## Data sheet

Feature	Value
Width	65.5 mm
Length	107.3 mm
Grid dimension	14.8 mm 14.9 mm
Max. number of valve positions	4
Operating pressure MPa	-0.09 ... 1 MPa
Working pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 ... 50 °C
Product weight	250 g
Pneumatic connection, port 2	M7 G1/8
Pneumatic connection, port 4	M7 G1/8
Materials note	Conforms to RoHS
Material of connecting plate	Aluminum die cast