


Non-return valve VABF-L1-14-H2

Part number: 8047365

FESTO

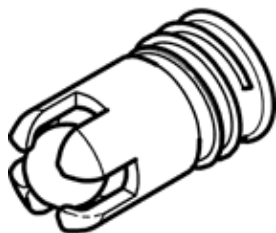

Data sheet

Feature	Value
Valve size	14 mm
Valve function	piloted non-return function
Operating pressure MPa	0.05 ... 0.8 MPa
Working pressure	0.5 ... 8 bar
Authorization	c UL us - Recognized (OL)
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 ... 60 °C
Product weight	1 g
Mounting type	Tapped
Materials note	Conforms to RoHS