


Common supply manifold OABM-P-G3-15-2

Part number: 8049144

FESTO

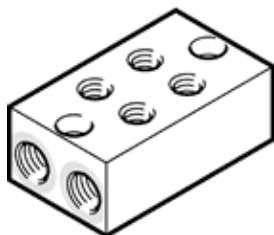

Data sheet

| Feature | Value |
|---|-------------------------------|
| No. of device positions | 2 |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Max. tightening torque | 3.3 Nm |
| Min. tightening torque | 0.3 Nm |
| Product weight | 59.6 g |
| Mounting type | with through hole |
| Pneumatic connection, port 1 | G1/8 |
| Materials note | Conforms to RoHS |
| Material of connecting plate | Wrought Aluminum alloy |