


# Idle return roller lever VAOM-R4-20-D2-32

Part number: 8049237

FESTO

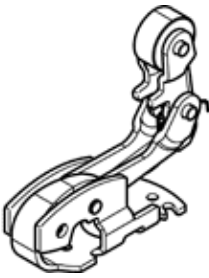

## Data sheet

Feature	Value
Width	20 mm
Type of actuation	mechanical
Assembly position	Movement plane
Design structure	Toggle lever
Type of piloting	direct
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Mounting type	Tightened
Materials note	Conforms to RoHS
Material mounting adaptor	steel, galvanized