


Parallel kit EAMM-U-60-S38-57AC-91

Part number: 8058946

FESTO

Suitable for electric drives.

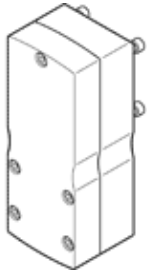

Data sheet

| Feature | Value |
|--------------------------|------------------------|
| Size | 60 |
| Assembly position | Any |
| Max. speed | 6,000 1/min |
| PWIS conformity | VDMA24364-B2-L |
| Storage temperature | -25 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Protection class | IP40 |
| Ambient temperature | -10 ... 60 °C |
| Mass moment of inertia | 26.7 kgmm ² |
| No-load driving torque | 0.07 Nm |
| Transferable torque | 3 Nm |
| Product weight | 1,150 g |
| Interface code, actuator | S38 |
| Interface code, motor in | 57AC |
| Materials note | Conforms to RoHS |