


Suction cup complete OGVM-55X115-AV-N-G14F

Part number: 8073867

FESTO

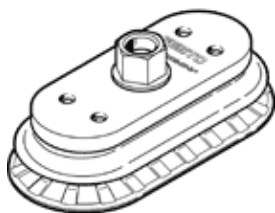

Data sheet

Feature	Value
Suction cup height compensator	13 mm
Min. workpiece radius	50 mm
Nominal size	8 mm
suction cup size	55x115 mm
suction cup volume	52 cm ³
Position of connection	on top
Assembly position	Any
Suction cup shape	Oval, bellows, 1.5 convolutions
Operating pressure MPa	-95 ... 0 kPa
Working pressure	-0.95 ... 0 bar
Operating pressure	-13.775 ... 0 psi
Nominal operating pressure	-60 kPa
Nominal working pressure	-0.6 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-A1-L
Ambient temperature	-20 ... 80 °C
Retention force at nominal operating pressure	200 N
Vertical lateral force at nominal operating pressure	234 N
Product weight	76 g
Mounting type	Via vacuum port
Vacuum connection	Female thread 1/4
Color	Black
Shore hardness	60 +/- 5
Material of threaded plug	Wrought Aluminum alloy
Materials note	Conforms to RoHS
Material suction cup	NBR