


Manifold strip

VABM-P7-18MB-G18-M5-6

Part number: 8076389

FESTO

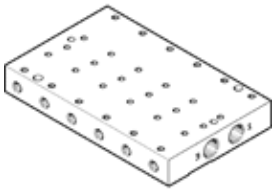

Data sheet

Feature	Value
Grid dimension	18 mm
Design structure	Connection direction underneath
Max. number of valve positions	6
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Max. tightening torque, valve mounting	0.6 Nm
Product weight	270 g
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	M5
Materials note	Conforms to RoHS
Material manifold	Wrought Aluminum alloy