


Mains filter CAMF-C6-F-C8-3A

Part number: 8088928

★ Core product range

FESTO

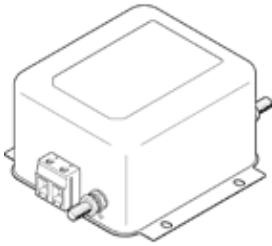

Data sheet

| Feature | Value |
|--|--|
| Short circuit strength | No |
| Acceptable current load at 40°C | 8 A |
| Operating voltage range AC | 0 ... 250 V |
| Line frequency | 0 ... 400 Hz |
| Insulation voltage | 1,100 V |
| Authorization | ENEC UL - Recognized (OL) c UL - Recognized (OL) |
| CE symbol (see declaration of conformity) | in accordance with EU RoHS directive |
| PWIS conformity | VDMA24364 zone III |
| Storage temperature | -25 ... 100 °C |
| Protection class | IP20 |
| Ambient temperature | -25 ... 100 °C |
| Product weight | 700 g |
| Mounting type | Mounting plate, bolted |
| Materials note | Conforms to RoHS |
| Assembly position | Horizontal |
| Electrical connection 1, function | Power supply |
| Electrical connection 1, connection type | Terminal strip |
| Electrical connection 1, connection technology | Screwed terminal |
| Electrical connection 1, number of pins/wires | 2 |
| Electrical connection 1, occupied pins/wires | 2 |
| Electrical connection 1, conductor cross section | 4 ... 6 mm ² |
| Electrical connection 2, function | Power supply |
| Electrical connection 2, connection type | Terminal strip |
| Electrical connection 2, connection technology | Screwed terminal |
| Electrical connection 2, number of pins/wires | 2 |
| Electrical connection 2, occupied pins/wires | 2 |
| Electrical connection 2, conductor cross section | 4 ... 6 mm ² |