 



# Pressure gauge PAGN-26-1M-G18S

Part number: 8088986

FESTO

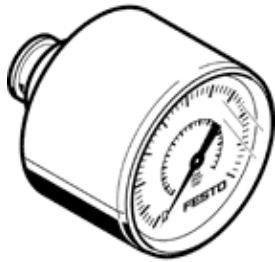

## Data sheet

Feature	Value
Indicating range [bar]	0 ... 10 bar
Display range	0 ... 1 MPa 0 ... 145 psi
Nominal size of pressure gauge	26
Design structure	Bourdon-tube pressure gauge
Mounting type	Line installation
Operating medium	Inert gases Neutral fluids
Operating pressure MPa	0 ... 1 MPa
Working pressure	0 ... 10 bar
Operating pressure	0 ... 145 psi
Alternating load factor	0.66
Measurement accuracy class	4
Protection class	IP43
Storage temperature	-5 ... 50 °C
Medium temperature	-5 ... 50 °C
Ambient temperature	-5 ... 50 °C
PWIS conformity	VDMA24364-B1/B2-L
Materials note	Conforms to RoHS
Position of connection	Rear side central
Pneumatic connection	G1/8, with sealing ring
Materials in contact with media	ABS Brass
Material of threaded plug	ABS
Material housing	ABS
Material screen	PS
Housing color	Black
Product weight	8 g
Note on operating and pilot medium	No acetylene No oxygen