


Braking resistance CACR-KL2-100-W1800

Part number: 8091545

FESTO

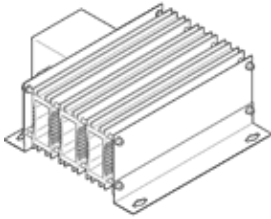

Data sheet

Feature	Value
Size	600
Assembly position	Free convection Vertical
Pulse energy, braking resistor at 380 V	10,800 Ws
Pulse energy, braking resistor at 780 V	10,800 Ws
Performance at 35% duty cycle and 20°C	1,800 W
Rated capacity, braking resistance	720 W
Rated output, braking resistor at 380 V	720 W
Rated output, braking resistor at 780 V	720 W
Resistance value	100 Ohm
Authorization	c CSA us (OL) c UL us - Recognized (OL)
PWIS conformity	VDMA24364 zone III
Protection class	IP65
Ambient temperature	0 ... 50 °C
Product weight	3,400 g
Mounting type	with through hole with accessories Optional
Materials note	Conforms to RoHS