


Parallel kit EAMM-U-87-T46-85AA-114

Part number: 8097655

FESTO

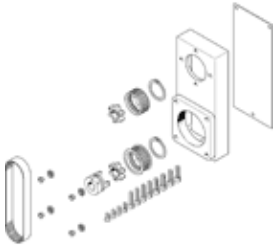

Data sheet

| Feature | Value |
|---------------------------|------------------------|
| Size | 87 |
| Center-to-center distance | 114 mm |
| Assembly position | Any |
| Gear unit ratio | 1:1 |
| Max. speed | 3,000 1/min |
| PWIS conformity | VDMA24364 zone III |
| Storage temperature | -20 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Protection class | IP40 |
| Ambient temperature | 0 ... 50 °C |
| Mass moment of inertia | 41.2 kgmm ² |
| No-load driving torque | 0.22 Nm |
| Transferable torque | 3 Nm |
| Product weight | 986 g |
| Interface code, actuator | T46 |
| Interface code, motor in | 85AA |
| Materials note | Conforms to RoHS |