


Exhaust plate

VABF-B14-M3-G14

Part number: 8099350

FESTO

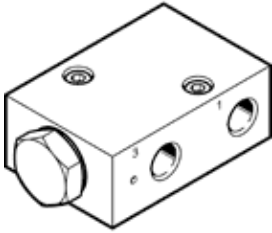

Data sheet

Feature	Value
Assembly position	Any
Working pressure	1.5 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364 zone III
Storage temperature	-20 ... 80 °C
Medium temperature	-20 ... 80 °C
Ambient temperature	-20 ... 80 °C
Product weight	280.5 g
Mounting type	with through hole
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 2	Flange 1/4 with NAMUR connection
Pneumatic connection, port 4	Flange 1/4 with NAMUR connection G1/4
Materials note	Conforms to RoHS
Material regulator housing	Wrought Aluminum alloy