


# Coupling EAMC-42-50-12-14-U

Part number: 8099432

FESTO

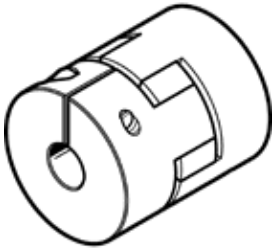

## Data sheet

Feature	Value
Holder diameter 1	12 mm
Holder diameter 2	14 mm
Size	42
Nominal length	50 mm
Assembly position	Any
Max. speed	6,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	34.8 kgmm <sup>2</sup>
Transferable torque	21 Nm
Product weight	143 g
Materials note	Conforms to RoHS