


# Connector VABD-B14-P1-N18

Part number: 8099629

FESTO

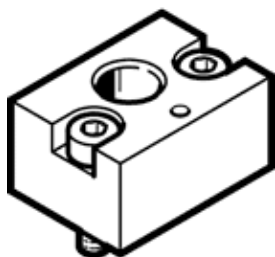

## Data sheet

Feature	Value
Assembly position	Any
Working pressure	1.5 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364 zone III
Storage temperature	-20 ... 60 °C
Medium temperature	-20 ... 60 °C
Ambient temperature	-20 ... 60 °C
Product weight	26 g
Mounting type	with through hole
Pneumatic connection, port 1	1/8 NPT
Materials note	Conforms to RoHS
Material of connecting plate	Wrought Aluminum alloy