


Manifold block-SET VABS-C12-6-S

Part number: 8122790

FESTO

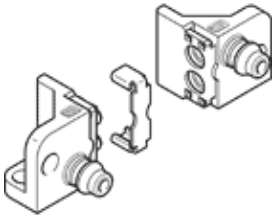

Data sheet

Feature	Value
Width	13 mm
Assembly position	Any
Design structure	Connection direction at side
Max. number of valve positions	Versions to customer requirements possible
Operating pressure MPa	-0.1 ... 0.7 MPa
Working pressure	-1 ... 7 bar
Operating medium	Compressed air to ISO 8573-1:2010 [6:4:1]
Note on operating and pilot medium	Maximum particle size: 5 µm
PWIS conformity	VDMA24364 zone III
Ambient temperature	5 ... 50 °C
Product weight	3 g
Mounting type	with through hole
Pneumatic connection, port 2	For tubing internal diameter 4 mm
Materials note	Conforms to RoHS
Material manifold	PBT