


# Manifold block-SET VABS-C12-6-S-B4

Part number: 8122791

FESTO

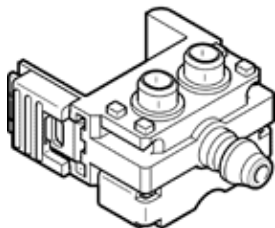

## Data sheet

Feature	Value
Width	6 mm
Assembly position	Any
Design structure	Connection direction at side
Max. number of valve positions	1
Operating pressure MPa	-0.1 ... 0.7 MPa
Working pressure	-1 ... 7 bar
Operating medium	Compressed air to ISO 8573-1:2010 [6:4:1]
Note on operating and pilot medium	Maximum particle size: 5 µm
PWIS conformity	VDMA24364 zone III
Ambient temperature	5 ... 50 °C
Product weight	1.1 g
Mounting type	with through hole
Pneumatic connection, port 2	For tubing internal diameter 2.5 mm
Materials note	Conforms to RoHS
Material manifold	PBT