


# Connector block

## VABM-C12-6M-M5-M3-10

Part number: 8122794

FESTO

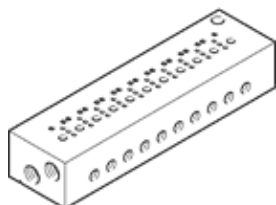

### Data sheet

Feature	Value
Width	20 mm
Assembly position	Any
Design structure	Connection direction underneath
Max. number of valve positions	10
Operating pressure MPa	-0.1 ... 0.7 MPa
Working pressure	-1 ... 7 bar
Operating medium	Compressed air to ISO 8573-1:2010 [6:4:1]
Note on operating and pilot medium	Maximum particle size: 5 µm
PWIS conformity	VDMA24364 zone III
Ambient temperature	5 ... 50 °C
Product weight	49.5 g
Mounting type	with through hole
Pneumatic connection, port 1	M5
Pneumatic connection, port 2	M3
Pneumatic connection, port 3	M5
Materials note	Conforms to RoHS
Material manifold	Wrought Aluminum alloy