


# Coupling EAMC-56-58-20-22

Part number: 8134825

FESTO

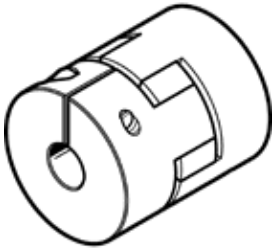

## Data sheet

Feature	Value
Holder diameter 1	20 mm
Holder diameter 2	22 mm
Size	56
Nominal length	58 mm
Assembly position	Any
Max. speed	5,500 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	129 kgmm <sup>2</sup>
Transferable torque	60 Nm
Product weight	281 g
Materials note	Conforms to RoHS