


Coupling EAMC-67-71-24-40-U

Part number: 8134949

FESTO

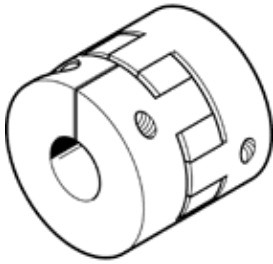

Data sheet

Feature	Value
Holder diameter 1	24 mm
Holder diameter 2	40 mm
Size	67
Nominal length	71 mm
Assembly position	Any
Max. speed	4,500 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	302 kgmm ²
Transferable torque	143 Nm
Product weight	429 g
Materials note	Conforms to RoHS