


# Power supply unit CACN-3A-7-5-G2

Part number: 8149583

FESTO

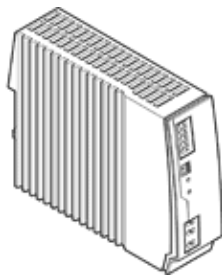

## Data sheet

Feature	Value
Width	42 mm
Height	130 mm
Length	160 mm
Assembly position	Free convection
Primary supply	Single-phase
Input current	1,2 - 2,9 A
Nominal output voltage DC	48 V
Nominal output current	5 A
Input voltage range AC	100 ... 240 V
Power failure buffering	15 ms
Line frequency	45 ... 65 Hz
Authorization	c UL us - Listed (OL)
CE symbol (see declaration of conformity)	according to EU-EMV guideline according to EU low voltage guideline
PWIS conformity	VDMA24364 zone III
Storage temperature	-40 ... 85 °C
Relative air humidity	95 %
Protection class	IP20
Ambient temperature	-25 ... 70 °C
Product weight	1,120 g
Mounting type	with top-hat rail
Materials note	Conforms to RoHS