


Power supply unit CACN-11A-7-20-G2

Part number: 8149585

FESTO

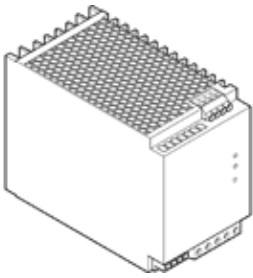

Data sheet

Feature	Value
Width	96 mm
Height	130 mm
Length	179 mm
Assembly position	Free convection
Primary supply	Three-phase
Input current	1,7 - 2,1 A
Nominal output voltage DC	48 V
Nominal output current	20 A
Input voltage range AC	400 ... 500 V
Power failure buffering	25 ms
Line frequency	45 ... 65 Hz
Authorization	c UL us - Listed (OL)
CE symbol (see declaration of conformity)	according to EU-EMV guideline according to EU low voltage guideline
PWIS conformity	VDMA24364 zone III
Storage temperature	-40 ... 85 °C
Relative air humidity	95 %
Protection class	IP20
Ambient temperature	-25 ... 70 °C
Product weight	2,500 g
Mounting type	with top-hat rail
Materials note	Conforms to RoHS