


# Connector kit DADG-AK-G8-20-10/30

Part number: 8152389

FESTO

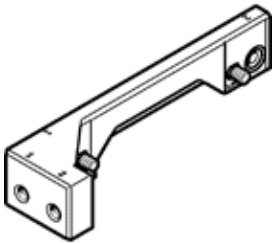

## Data sheet

Feature	Value
Size	20
Stroke	10 ... 30 mm
Operating pressure MPa	0.1 ... 0.8 MPa
Working pressure	1 ... 8 bar
Operating pressure	14.5 ... 116 psi
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Max. tightening torque	3 Nm
Tightening torque tolerance	± 10 %
Max. tightening torque, pneumatic connection 1	3 Nm
Product weight	36.3 g
Pneumatic connection	G1/8
Material adapter	Epoxy resin
Material seals	FPM
Material screws	Coated steel