


Subbase VMPA1-AP-4-EMM-8-SL

Part number: 8157744

FESTO

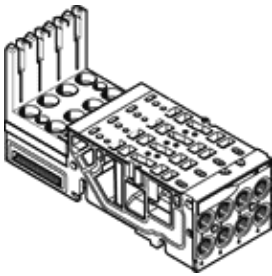

Data sheet

Feature	Value
Width	42 mm
Length	107.3 mm
Grid dimension	10.5 mm
Max. number of valve positions	4
Operating pressure MPa	-0.09 ... 1 MPa
Working pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364 zone III
Storage temperature	-20 ... 60 °C
Ambient temperature	-5 ... 50 °C
Product weight	180 g
Pneumatic connection, port 2	M7
Pneumatic connection, port 4	M7
Materials note	Conforms to RoHS
Material of connecting plate	Aluminum die cast