


Shock absorber DYEF-G8-S-M10-Y1

Part number: 8159474

FESTO

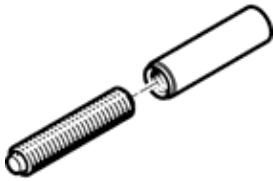

Data sheet

Feature	Value
Size	M10
Stroke	1 mm
Cushioning	P cushioning without metal fixed stop
Assembly position	Any
Position detection	No
Max. impact speed	0.8 m/s
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	0 ... 60 °C
Cushioning length	1 mm
Max. tightening torque	3 Nm
Max. energy consumption per stroke	0.25 J
Product weight	26 g
Mounting type	with threaded sleeve
Materials note	Conforms to RoHS
Material seals	NBR
Material housing	High alloy steel