


Check valve VBNF-CBA-Q6-Q6

Part number: 8193270

FESTO

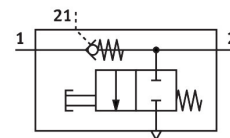

Data sheet

Feature	Value
Valve function	Non-return function
Pneumatic connection 1	QS-6
Pneumatic connection 2	QS-6
Pilot air port 21	QS-6
Actuation type	Manual
Standard nominal flow rate	260 l/min
Operating pressure	1 MPa 10 bar
Pilot pressure MPa	0.2 MPa...1 MPa
Pilot pressure	2 bar...10 bar
Pilot pressure psi	29 psi...145 psi
Ambient temperature	-10 °C...60 °C
Housing material	PBT
Housing colour	Gray
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Mounting position	Any
Actuation type, piloted non-return function	Pneumatic
Manual exhaust function	Non-detenting
Operating pressure for entire temperature range	0.2 bar...10 bar
Standard flow rate 1->2 (6-0)	500 l/min
Standard nominal flow rate 1->2 (6-5)	260 l/min
Switching time off	9 ms
On switching time	6 ms
Explosion prevention and protection	Zone 2 (ATEX) Zone 22 (ATEX)
Information on operating and pilot media	Operation with oil lubrication possible
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C...70 °C
Temperature of medium	-10 °C...60 °C
Pilot medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Product weight	23.3 g

Feature	Value
Covering material	ES-BE
Note on materials	RoHS-compliant
Cover material	PBT
Seals material	NBR
Releasing ring material	POM