


Axial kit EAMM-A-S38-60RA-G2

Part number: 8197484

FESTO

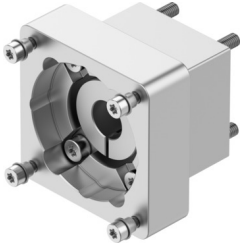

Data sheet

Feature	Value
Nominal length	49 mm
Mounting position	Any
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	5.87 kgmm ²
Transferable torque	6.5 Nm
Product weight	290 g
Interface code, actuator	S38
Interface code, motor in	60RA
Note on materials	RoHS-compliant