


# Suction cup with connector OGVM-20-A-N-RA

Part number: 8213231

FESTO

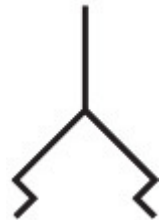

## Data sheet

| Feature                                     | Value                                                       |
|---------------------------------------------|-------------------------------------------------------------|
| Suction cup height compensation             | 5.8 mm                                                      |
| Min. workpiece radius                       | 12.5 mm                                                     |
| Nominal width                               | 4 mm                                                        |
| Suction cup diameter                        | 20 mm                                                       |
| Suction cup volume                          | 2 cm <sup>3</sup>                                           |
| Connection position                         | Top                                                         |
| Mounting position                           | Any                                                         |
| Suction cup shape                           | Round bellows, 1.5 convolutions                             |
| Operating pressure                          | -95 kPa...0 kPa<br>-0.95 bar...0 bar<br>-13.775 psi...0 psi |
| Nominal operating pressure                  | -60 kPa<br>-0.6 bar<br>-8.7 psi                             |
| Operating medium                            | Atmospheric air based on ISO 8573-1:2010 [7:::-]            |
| Corrosion resistance class (CRC)            | 2 - Moderate corrosion stress                               |
| LABS (PWIS) conformity                      | VDMA24364-A1/A2-L                                           |
| Ambient temperature                         | -20 °C...80 °C                                              |
| Holding force at nominal operating pressure | 15 N                                                        |
| Lateral force at nominal operating pressure | 15 N                                                        |
| Product weight                              | 25 g                                                        |
| Type of mounting                            | Via vacuum connection                                       |
| Vacuum connection                           | Rectangular adapter RA                                      |
| Color                                       | Black                                                       |
| Shore hardness                              | 60 +/- 5                                                    |
| Material of screwed plug                    | Wrought aluminum alloy                                      |
| Note on materials                           | RoHS-compliant                                              |
| Suction cup material                        | NBR                                                         |