


Distributor block FR-12-PK-3-B

Part number: 8761

FESTO

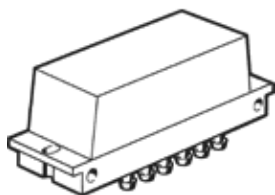

Data sheet

| Feature | Value |
|---|---|
| Nominal size | 2.5 mm |
| Assembly position | Any |
| Operating pressure complete temperature range | 0 ... 8 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| PWIS conformity | VDMA24364-B1/B2-L |
| Number of outputs | 12 |
| Number of supply lines | 1 |
| Pneumatic connection, port 1 | Female thread 1/4 |
| Pneumatic connection, port 2 | For tubing outside diameter 4 mm |
| Materials note | Conforms to RoHS |
| Material housing | Aluminum die cast |