


# Clevis foot mounting LN-125

Part number: 9036

FESTO

For swivel mounting of cylinders DNC, DNGU, DNGUT, DNG, DNU, AEVU, ADVU, ADVUP, ADVUP.

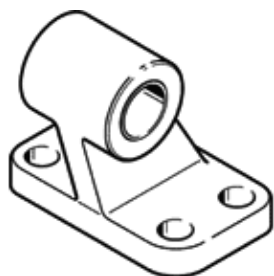

## Data sheet

Feature	Value
Size	125
Based on the standard	ISO 15552 (previously also VDMA 24652, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 ... 150 °C
Product weight	2,632 g
Materials note	Conforms to RoHS
Material mounting	Nodular graphite cast iron