


# Adapter AD-G1/8-1/8NPT-I

Part number: 9395

FESTO

Female thread one side, male thread on the other.

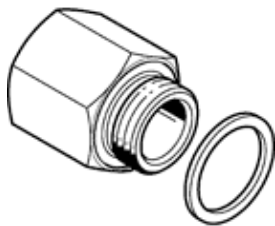

## Data sheet

Feature	Value
Nominal size	5.95 mm
Operating pressure complete temperature range	-0.95 ... 10 bar
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Max. tightening torque, pneumatic connection 1	6 Nm
Max. tightening torque, pneumatic connection 2	7 Nm
Nominal tightening torque	10.55 Nm
Tolerance for nominal tightening torque	± 20 %
Product weight	10.38 g
Pneumatic connection, port 1	Male thread G1/8
Pneumatic connection, port 2	Female thread 1/8 NPT
Materials note	Conforms to RoHS
Material seals	PVC
Material housing	steel, galvanized