


Adapter AD-G3/8-3/8NPT-I

Part number: 9397

FESTO

Female thread one side, male thread on the other.

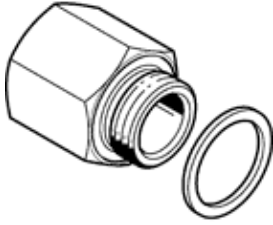

Data sheet

Feature	Value
Nominal size	11.5 mm
Operating pressure complete temperature range	-0.95 ... 10 bar
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Max. tightening torque, pneumatic connection 1	25 Nm
Max. tightening torque, pneumatic connection 2	22 Nm
Nominal tightening torque	38.5 Nm
Tolerance for nominal tightening torque	± 20 %
Product weight	25.3 g
Pneumatic connection, port 1	Male thread G3/8
Pneumatic connection, port 2	Female thread 3/8 NPT
Materials note	Conforms to RoHS
Material seals	PVC
Material housing	steel, galvanized