


# Adapter AD-1/8NPT-G1/8-I

Part number: 9624

FESTO

Female thread one side, male thread on the other.

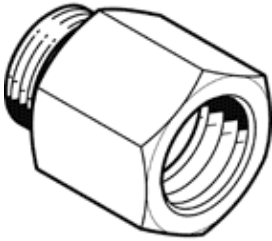

## Data sheet

Feature	Value
Nominal size	5.95 mm
Operating pressure complete temperature range	-0.95 ... 10 bar
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Max. tightening torque, pneumatic connection 1	7 Nm
Max. tightening torque, pneumatic connection 2	6 Nm
Product weight	9.5 g
Pneumatic connection, port 1	Male thread 1/8 NPT
Pneumatic connection, port 2	Female thread G1/8
Materials note	Conforms to RoHS
Material seals	PVC
Material housing	steel, galvanized