


Adapter AD-1/4NPT-G1/4-I

Part number: 9625

FESTO

Female thread one side, male thread on the other.

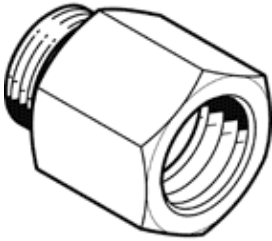

Data sheet

| Feature | Value |
|--|--------------------------|
| Nominal size | 7.95 mm |
| Operating pressure complete temperature range | -0.95 ... 10 bar |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -10 ... 60 °C |
| Max. tightening torque, pneumatic connection 1 | 12 Nm |
| Max. tightening torque, pneumatic connection 2 | 11 Nm |
| Product weight | 21 g |
| Pneumatic connection, port 1 | Male thread 1/4 NPT |
| Pneumatic connection, port 2 | Female thread 1/4 |
| Materials note | Conforms to RoHS |
| Material seals | PVC |
| Material housing | steel, galvanized |