

 

# Pneumatic limit valve RWN/O-3-1/8-B

Part number: 9694

FESTO

With installation dimensions and point of actuation in accordance with  
DIN 43694

This type is suitable for vacuum.

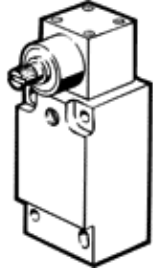

## Data sheet

Feature	Value
Valve function	3/2 open/closed, monostable
Standard nominal flow rate	120 l/min
Working pressure	-0.95 ... 8 bar
PWIS conformity	VDMA24364-B2-L