
 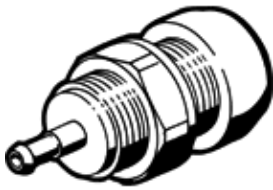


# Pressure indicator OH-10

Part number: 9791

FESTO



## Data sheet

Feature	Value
Operating pressure MPa	0.14 ... 0.8 MPa
Working pressure	1.4 ... 8 bar
Operating pressure	20.3 ... 116 psi
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 80 °C
Product weight	4 g
Pneumatic connection	Barbed fitting PK-3
Materials note	Conforms to RoHS