 



Ventil VOFC-LT-M32C-MC-N14-FN

Broj artikla: 8122933

FESTO

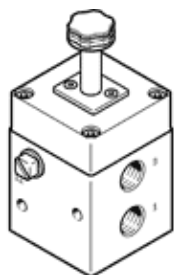

Tehnički podaci

Svojstvo	Vrijednost
Normalni nazivni protok	703 l/min
Operating pressure MPa	0,1 ... 0,8 MPa
Pogonski tlak	1 ... 8 bar
Mehanička zaštita	IP65
Mjesto izdavanja certifikata	TÜV 968/V 1251.00/21
Sigurnosna funkcija	Safe venting
Safety Integrity Level (SIL)	Product can be used in SRP/CS up to SIL 3 (high demand) do SIL 3 načina niskih zahtjeva
Uputa za pogonski tlak	0 - 0.8 MPa with external pilot air
Klasa korozione otpornosti KBK	4 - vrlo visoka otpornost na koroziju
PWIS conformity	VDMA24364 zone III
Materijal - napomena	RoHS sukladno