


# Pajungimo kabelis SIM-K-GD-5-PU

Gaminio numeris: 164256

FESTO

Jutkliams ir priartėjimo jungikliams.

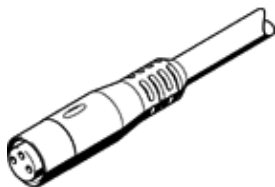

## Tech. Duomenys

Savybės	Reikšmė
Atitinka standartus	Core colours and connection numbers to EN 60947-5-2 EN 61076-2-104 EN 61984
Cable identification	Without inscription label holder
Prijungimo dažnis	100
Electrical connection 1, function	Field device side
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištuko lizdas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	M8 snap-locking A-coded to EN 61076-2-104
Electrical connection 1, number of pins/wires	3
Electrical connection 1, occupied pins/wires	3
Electrical connection 1, type of mounting	Snap-in locking
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabelis
Electrical connection 2, connection technology	atviri laidai
Electrical connection 2, number of pins/wires	3
Electrical connection 2, occupied pins/wires	3
Nominalus DC įtampos lygis	0 ... 60 V
Nominalus AC įtampos lygis	0 ... 60 V
Leistina srovės apkrova prie 40°C	3 A
Atsparumas smūgiams	1,5 kV
Kabelio ilgis	5 m
Kabelio priedas	Standartas
Laido bandymo sąlygos	Atsparumas lenkimui pagal Festo normas, bandymo sąlygos pagal užklausimą. Bandymas pagal užklausimą Energy chain: > 5 million cycles, bending radius 28 mm
Bending radius, fixed cable installation	≥ 23 mm
Bending radius, flexible cable installation	≥ 46 mm
Kabelio skersmuo	4,5 mm
Kabelio skersmens tolerancija	± 0,1 mm
Kabelio struktūra	3x0,25
Nominalus laidininko skerspjūvis	0,25 mm <sup>2</sup>
Laido galai	Laido antgalis
Apsaugos klasė	IP65 IP67
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-25 ... 70 °C
Aplinkos temperatūra esant lankščiai kabelių instaliacijai	-5 ... 70 °C
Saugojimo temperatūra	-25 ... 70 °C
CE ženklas (žr. deklaraciją)	atitinka EU reikalavimus žemose įtampose in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment

Savybės	Reikšmė
	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS Be halogeno
Užterštumo laipsnis	3
Atsparumo korozijai klasė CRC	4 - Very high corrosion stress
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	pilkas
Material housing	TPE-U(PUR)
Korpuso spalva	Juodas
Material seals	NBR
Material electrical contact	Brass, gold-plated
Material insulation	PP