 



Kištukas SEA-GS-7

Gaminio numeris: 18666

FESTO

Skirstytuvų saloms.

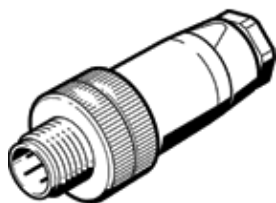

Tech. Duomenys

Savybės	Reikšmė
Parentas standartu	EN 61076-2-101
Montavimo tipas	su sriegine įvove
Cable outlet	Tiesus
Produkto svoris	17 g
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištukas
Electrical connection 1, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 1, number of pins/wires	4
Electrical connection 1, type of mounting	Screw-type lock with longitudinal knurl
Electrical connection 2, connection technology	Įsuktas terminalas
Electrical connection 2, number of pins/wires	4
Nominalus DC įtampos lygis	0 ... 250 V
Nominalus AC įtampos lygis	0 ... 250 V
Leistina srovės apkrova prie 40°C	4 A
Atsparumas smūgiams	2,5 kV
Kabelio prijungimas	Pg7
Kabelio skersmuo	3,3 ... 6 mm
Leistinas kabelio skersmuo	4 ... 6 mm
Nominalus laidininko skerspjūvis	0,14 ... 0,75 mm ²
Apsaugos klasė	IP67
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-40 ... 85 °C
CE ženklas (žr. deklaraciją)	atitinka EU reikalavimus žemose įtampose
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Užterštumo laipsnis	3
Atsparumo korozijai klasė CRC	2 - Moderate corrosion stress
Material housing	PBT
Korpuso spalva	Juodas
Material screw-type lock	PBT
Material seals	CR FPM
Material electrical contact	Žalvaris Balta bronz padengta