


Adresavimo įrenginio kabelis KASI-ADR

Gaminio numeris: 18960

FESTO

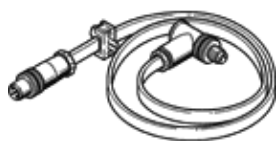

Tech. Duomenys

Savybės	Reikšmė
Protokolas	AS-Interface
Konstrukcija	T-distributor with cables on both sides
Distributor type	2 to 1
Papildomos funkcijos	Connecting the programming device to an ASInterface component via AS-i flat cable
Cable identification	Without inscription label holder
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištuko lizdas
Electrical connection 1, cable outlet	Angled
Electrical connection 1, connection technology	AS-Interface
Electrical connection 1, number of pins/wires	2
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, type of mounting	Plug-in
Electrical connection 2, function	Field device side
Electrical connection 2, design	apvalus
Electrical connection 2, connection type	Kištuko lizdas
Electrical connection 2, cable outlet	Tiesus
Electrical connection 2, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 2, number of pins/wires	4
Electrical connection 2, occupied pins/wires	2
Electrical connection 2, type of mounting	Plug-in
Electrical connection 3, function	Controller side
Electrical connection 3, design	apvalus
Electrical connection 3, connection type	Kištukas
Electrical connection 3, cable outlet	Angled
Electrical connection 3, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 3, number of pins/wires	4
Electrical connection 3, occupied pins/wires	2
Electrical connection 3, type of mounting	Plug-in
Nominalus DC įtampos lygis	0 ... 48 V
Nominalus AC įtampos lygis	0 ... 48 V
Leistina srovės apkrova prie 40°C	3 A
Atsparumas smūgiams	0,5 kV
Cable length 1	2,4 m
Cable length 2	0,1 m
Kabelio priedas	Standartas
Laido bandymo sąlygos	Bandymas pagal užklausimą
Kabelio struktūra	2x1,5
Nominalus laidininko skerspjūvis	1,5 mm ²
Apsaugos klasė	IP20
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-40 ... 85 °C
Aplinkos temperatūra esant lankščiai kabelių instaliacijai	-25 ... 80 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions

Savybės	Reikšmė
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Užterštumo laipsnis	2
Material cable sheath	Gumos mišinys
Kabelio apvalkalo spalva	geltonas
Korpuso spalva	Juodas