 



DUO kabelis

NEDU-L1R2-V9-M12G8-E-LE5-5R1-LE3-5R2

Gaminio numeris: 2903567

FESTO

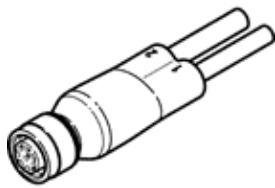

Tech. Duomenys

Savybės	Reikšmė
Paremtas standartu	EN 61076-2-101
Konstrukcija	Y-distributor with cable on field device and controller sides
Distributor type	1 to 2
Papildomos funkcijos	Connection of sensor and controller to proportional pressure regulator
Cable identification	Without inscription label holder
Produkto svoris	377 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištuvo lizdas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 1, number of pins/wires	8
Electrical connection 1, occupied pins/wires	6
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabelis
Electrical connection 2, connection technology	atviri laidai
Electrical connection 2, number of pins/wires	5
Electrical connection 2, occupied pins/wires	5
Electrical connection 3, function	Field device side
Electrical connection 3, connection type	Kabelis
Electrical connection 3, connection technology	atviri laidai
Electrical connection 3, number of pins/wires	3
Electrical connection 3, occupied pins/wires	3
Nominalus DC įtampos lygis	0 ... 30 V
Nominalus AC įtampos lygis	0 ... 30 V
Leistina srovės apkrova prie 40°C	2 A
Atsparumas smūgiams	0,8 kV
Cable length 1	5 m
Cable length 2	5 m
Cable diameter 1	5,3 mm
Cable diameter 2	4,5 mm
Kabelio struktūra	3x0,25 5x0,25 Ekranuotas
Nominalus laidininko skerspjūvis	0,25 mm ²
Apsaugos klasė	IP65 IP67
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-25 ... 80 °C
Aplinkos temperatūra esant lankščiai kabelių instaliacijai	-5 ... 80 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Užterštumo laipsnis	3

Savybės	Reikšmė
Atsparumo korozijai klasė CRC	2 - Moderate corrosion stress
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	Juodas
Material housing	TPE-U(PUR)
Korpuso spalva	Juodas
Material screw-type lock	Nickel-plated brass
Material seals	FPM
Material electrical contact	Brass, gold-plated
Material insulation	PVC