 



# Pajungimo kabelis

## NEBV-A1W3-K-0.6-N-M12W3

Gaminio numeris: 3579462

FESTO

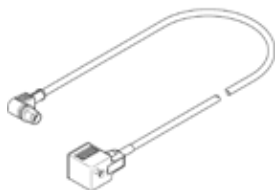

## Tech. Duomenys

Savybės	Reikšmė
Leidimas	c CSA us (OL)
Cable identification	Without inscription label holder
Produkto svoris	100 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištuvo lizdas
Electrical connection 1, cable outlet	Angled
Electrical connection 1, connection technology	Plug pattern type A based on EN 175301-803
Electrical connection 1, number of pins/wires	4
Electrical connection 1, occupied pins/wires	4
Electrical connection 1, type of mounting	Elektromagnetiniame skirstytuve su M3 centriniu varžtu
Electrical connection 2, function	Controller side
Electrical connection 2, design	apvalus
Electrical connection 2, connection type	Kištukas
Electrical connection 2, cable outlet	Angled
Electrical connection 2, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 2, number of pins/wires	5
Electrical connection 2, occupied pins/wires	3
Electrical connection 2, type of mounting	Screw locking with hex SW13
Nominalus DC įtampos lygis	0 ... 110 V
Nominali darbinė nuolatinė įtampa	110 V
Nominalus AC įtampos lygis	0 ... 110 V
Nominali darbinė kintama įtampa	110 V
Leistina srovės apkrova prie 40°C	1 A
Atsparumas smūgiams	1,5 kV
Apsaugotas įžeminimas	Galimas
Kabelio ilgis	0,6 m
Kabelio priedas	Standartas
Laido bandymo sąlygos	Bandymas pagal užklausimą
Kabelio skersmuo	5,9 mm
Kabelio skersmens tolerancija	± 0,3 mm
Kabelio struktūra	3x0,75
Apsaugos klasė	IP67
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-25 ... 80 °C
Aplinkos temperatūra esant lankščiai kabelių instaliacijai	-25 ... 80 °C
CE ženklas (žr. deklaraciją)	atitinka EU reikalavimus žemose įtampose in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
Informacija	atitinka RoHS
Užterštumo laipsnis	3
Atsparumo korozijai klasė CRC	2 - Moderate corrosion stress
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	pilkas

Savybės	Reikšmė
Material housing	TPE-U(PUR)
Korpuso spalva	Juodas
Material of union nut	Cinkuota Nikeliuota
Material insulation	PP