 



Variklio kabelis

NEBM-SM12G8-E-25-Q5-LE6

Gaminio numeris: 5105620

FESTO

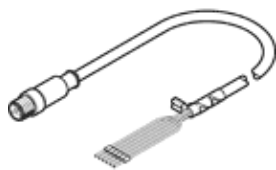

Tech. Duomenys

| Savybės | Reikšmė |
|--|--|
| Cable identification | Without inscription label holder |
| Electrical connection 1, function | Field device side |
| Electrical connection 1, design | apvalus |
| Electrical connection 1, connection type | Kištukas |
| Electrical connection 1, cable outlet | Tiesus |
| Electrical connection 1, connection technology | M12x1, A-coded in accordance with EN 61076-2-101 |
| Electrical connection 1, number of pins/wires | 8 |
| Electrical connection 1, occupied pins/wires | 6 |
| Electrical connection 2, function | Controller side |
| Electrical connection 2, connection type | Kabelis |
| Electrical connection 2, connection technology | atviri laidai |
| Electrical connection 2, number of pins/wires | 6 |
| Electrical connection 2, occupied pins/wires | 6 |
| Nominalus DC įtampos lygis | 0 ... 72 V |
| Nominali darbinė nuolatinė įtampa | 24 V |
| Kabelio ilgis | 25 m |
| Kabelio priedas | Suitable for energy chains |
| Bending radius, flexible cable installation | ≥ 62 mm |
| Kabelio skersmuo | 6,2 mm |
| Kabelio struktūra | 6x0,34 Ekranuotas |
| Nominalus laidininko skerspjūvis | 0,34 mm ² |
| Laido galai | Laido antgalis |
| Apsaugos klasė | IP65 |
| Note on degree of protection | Sumontuotas |
| Aplinkos temperatūra | -40 ... 80 °C |
| Aplinkos temperatūra esant lankščiai kabelių instaliacijai | -5 ... 80 °C |
| CE ženklas (žr. deklaraciją) | in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK RoHS instructions |
| PWIS conformity | VDMA24364-B2-L |
| Informacija | atitinka RoHS |
| Material cable sheath | TPE-U(PUR) |
| Kabelio apvalkalo spalva | pilkas |