

# Kabelis

## KMP6-15P-12-5

 

Gaminio numeris: 527544

Classic - nicht für Neukonstruktionen verwenden

Skirstytuvų salai CPV-SC, su Sub-D 15 polių kištuku, 5 m ilgio.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

FESTO

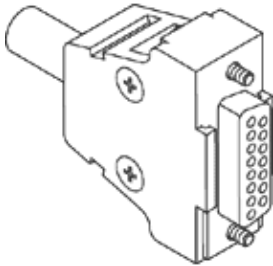

## Tech. Duomenys

| Savybės                                                    | Reikšmė                              |
|------------------------------------------------------------|--------------------------------------|
| Atitinka standartus                                        | DIN 41652                            |
| Cable identification                                       | Without inscription label holder     |
| Prijungimo dažnis                                          | 50                                   |
| Produkto svoris                                            | 585 g                                |
| Electrical connection 1, function                          | Field device side                    |
| Electrical connection 1, design                            | kampinis                             |
| Electrical connection 1, connection type                   | Kištuko lizdas                       |
| Electrical connection 1, cable outlet                      | Tiesus                               |
| Electrical connection 1, connection technology             | Sub-D                                |
| Electrical connection 1, number of pins/wires              | 15                                   |
| Electrical connection 1, occupied pins/wires               | 15                                   |
| Electrical connection 1, type of mounting                  | 2 screws 4-40 UNC                    |
| Electrical connection 2, function                          | Controller side                      |
| Electrical connection 2, connection type                   | Kabelis                              |
| Electrical connection 2, connection technology             | atviri laidai                        |
| Electrical connection 2, number of pins/wires              | 15                                   |
| Electrical connection 2, occupied pins/wires               | 15                                   |
| Nominalus DC įtampos lygis                                 | 0 ... 30 V                           |
| Nominali darbinė nuolatinė įtampa                          | 24 V                                 |
| Leistina srovės apkrova prie 40°C                          | 2,8 A                                |
| Atsparumas smūgiams                                        | 1 kV                                 |
| Kabelio ilgis                                              | 5 m                                  |
| Kabelio priedas                                            | Standartas                           |
| Laido bandymo sąlygos                                      | Bandyamas pagal užklausimą           |
| Bending radius, fixed cable installation                   | ≥ 86 mm                              |
| Bending radius, flexible cable installation                | ≥ 129 mm                             |
| Kabelio skersmuo                                           | 8,6 mm                               |
| Kabelio skersmens tolerancija                              | ± 0,25 mm                            |
| Kabelio struktūra                                          | 15x0,34                              |
| Nominalus laidininko skerspjuvis                           | 0,34 mm <sup>2</sup>                 |
| Laido galai                                                | Cut off bluntly                      |
| Apsaugos klasė                                             | IP40                                 |
| Note on degree of protection                               | Sumontuotas                          |
| Aplinkos temperatūra                                       | -25 ... 70 °C                        |
| Aplinkos temperatūra esant lankščiai kabelių instaliacijai | -5 ... 70 °C                         |
| Saugojimo temperatūra                                      | -20 ... 75 °C                        |
| CE ženklas (žr. deklaraciją)                               | in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity)               | To UK RoHS instructions              |
| PWIS conformity                                            | VDMA24364-B2-L                       |
| Informacija                                                | atitinka RoHS                        |
| Užterštumo laipsnis                                        | 2                                    |
| Material cable sheath                                      | PVC                                  |

| Savybės                     | Reikšmė                  |
|-----------------------------|--------------------------|
| Kabelio apvalkalo spalva    | pilkas                   |
| Material housing            | PBT-sustiprintas         |
| Korpuso spalva              | pilkas                   |
| Material screw-type lock    | Nickel-plated brass      |
| Material electrical contact | Gold-plated copper alloy |