

Kabelis

KMP6-26P-16-5

 

Gaminio numeris: 527547

Classic - nicht für Neukonstruktionen verwenden

Skirstytuvų salai CPV-SC, su Sub-D 26 polių kištuku, 5 m ilgio.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

FESTO

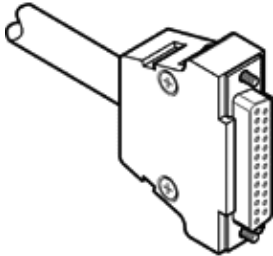

Tech. Duomenys

| Savybės | Reikšmė |
|--|--------------------------------------|
| Atitinka standartus | DIN 41652 |
| Cable identification | Without inscription label holder |
| Prijungimo dažnis | 50 |
| Produkto svoris | 570 g |
| Electrical connection 1, function | Field device side |
| Electrical connection 1, design | kampinis |
| Electrical connection 1, connection type | Kištuko lizdas |
| Electrical connection 1, cable outlet | Tiesus |
| Electrical connection 1, connection technology | Sub-D |
| Electrical connection 1, number of pins/wires | 26 |
| Electrical connection 1, occupied pins/wires | 20 |
| Electrical connection 1, type of mounting | 2 screws 4-40 UNC |
| Electrical connection 2, function | Controller side |
| Electrical connection 2, connection type | Kabelis |
| Electrical connection 2, connection technology | atviri laidai |
| Electrical connection 2, number of pins/wires | 20 |
| Electrical connection 2, occupied pins/wires | 20 |
| Nominalus DC įtampos lygis | 0 ... 30 V |
| Nominali darbinė nuolatinė įtampa | 24 V |
| Leistina srovės apkrova prie 40°C | 2,8 A |
| Atsparumas smūgiams | 1 kV |
| Kabelio ilgis | 5 m |
| Kabelio priedas | Standartas |
| Laido bandymo sąlygos | Bandyamas pagal užklausimą |
| Bending radius, fixed cable installation | ≥ 88 mm |
| Bending radius, flexible cable installation | ≥ 132 mm |
| Kabelio skersmuo | 8,8 mm |
| Kabelio skersmens tolerancija | ± 0,25 mm |
| Kabelio struktūra | 20x0,25 |
| Nominalus laidininko skerspjuvis | 0,25 mm ² |
| Laido galai | Cut off bluntly |
| Apsaugos klasė | IP40 |
| Note on degree of protection | Sumontuotas |
| Aplinkos temperatūra | -25 ... 70 °C |
| Aplinkos temperatūra esant lankščiai kabelių instaliacijai | -5 ... 70 °C |
| Saugojimo temperatūra | -25 ... 75 °C |
| CE ženklas (žr. deklaraciją) | in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK RoHS instructions |
| PWIS conformity | VDMA24364-B2-L |
| Informacija | atitinka RoHS |
| Užterštumo laipsnis | 2 |
| Material cable sheath | PVC |

| Savybės | Reikšmė |
|-----------------------------|--------------------------|
| Kabelio apvalkalo spalva | pilkas |
| Material housing | PBT-sustiprintas |
| Korpuso spalva | pilkas |
| Material screw-type lock | Nickel-plated brass |
| Material electrical contact | Gold-plated copper alloy |