

 

Variklio kabelis KMTR-DC-SUB-15-M12-2,5

Gaminio numeris: 538917
Nebetiekiamas produktas

FESTO

elektrinėms Mini kreipiamosioms SLTE arba lygiagretiems
griebtuvams HGPLE sujungti su valdikliu SFC-DC.

Type to be discontinued. Available until 2020. See Support Portal for
alternative products.

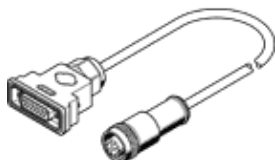

Tech. Duomenys

Savybės	Reikšmė
Cable identification	su priedais
Electrical connection 1, function	Field device side
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištuko lizdas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	M12x1 A-coded to EN 61076-2-101
Electrical connection 1, number of pins/wires	12
Electrical connection 1, occupied pins/wires	11
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, function	Controller side
Electrical connection 2, design	kampinis
Electrical connection 2, connection type	Kištukas
Electrical connection 2, cable outlet	Tiesus
Electrical connection 2, connection technology	Sub-D
Electrical connection 2, number of pins/wires	15
Electrical connection 2, occupied pins/wires	11
Electrical connection 2, type of mounting	2x screw 4-40 UNC-2A
Nominalus DC įtampos lygis	0 ... 24 V
Leistina srovės apkrova prie 40°C	1 A
Atsparumas smūgiams	0,5 kV
Kabelio ilgis	2,5 m
Kabelio priedas	tinkamas lanksčiai kabelio apsaugai
Bending radius, fixed cable installation	≥ 50 mm
Bending radius, flexible cable installation	≥ 80 mm
Kabelio skersmuo	8 mm
Kabelio struktūra	4x(2x0,14)D+3x0,14 Ekranuotas
Nominalus laidininko skerspjūvis	0,14 mm ²
Apsaugos klasė	IP67
Note on degree of protection	Sumontuotas
Aplinkos temperatūra esant lanksčiai kabelių instaliacijai	-25 ... 70 °C
Informacija	Turi PWIS medžiagų atitinka RoHS
Užterštumo laipsnis	2
Atsparumo korozijai klasė CRC	0 - No corrosion stress
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	oranžinis