


# Pajungimo kabelis NEBV-S1W37-E-10-LE26

Gaminio numeris: 539245

FESTO

Skirstytuvų salų VTSA ir VTSA-F daugiapolinei jungčiai, iki 22 skirstytuvų ričių, su Sub-D kištuko lizdu, 26-polių, tinkamas naudoti apsauginiuose vikšruose.

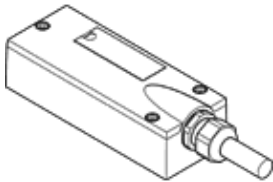

## Tech. Duomenys

Savybės	Reikšmė
Naudojimo sritis	Only for multi-pin plug connection valve terminal VTSA/VTSA-F
Atitinka standartus	DIN 47100
Cable identification	With inscription label holder
Produkto svoris	1.859 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištuko lizdas
Electrical connection 1, cable outlet	Angled
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	37
Electrical connection 1, occupied pins/wires	26
Electrical connection 1, type of mounting	3x M4 screws
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabelis
Electrical connection 2, connection technology	atviri laidai
Electrical connection 2, number of pins/wires	26
Electrical connection 2, occupied pins/wires	26
Nominalus DC įtampos lygis	0 ... 30 V
Leistina srovės apkrova prie 40°C	2 A
Atsparumas smūgiams	1 kV
Kabelio ilgis	10 m
Kabelio priedas	Suitable for energy chains
Laido bandymo sąlygos	Bandyamas pagal užklausimą
Bending radius, fixed cable installation	≥ 42 mm
Bending radius, flexible cable installation	≥ 104 mm
Kabelio skersmuo	10,4 mm
Kabelio struktūra	26x0,34
Nominalus laidininko skerspjūvis	0,34 mm <sup>2</sup>
Apsaugos klasė	IP65 NEMA 4
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-5 ... 50 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Atsparumo korozijai klasė CRC	2 - Moderate corrosion stress
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	pilkas
Material housing	PA
Material insulation	PVC