 



# Signalo keitiklis SVE4-IS-R-HM8-2N-M8

Gaminio numeris: 544221

FESTO

Pakeičia analoginį jutiklio signalą į valdymo signalus išėjime

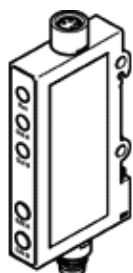

## Tech. Duomenys

Savybės	Reikšmė
Leidimas	RCM Mark c UL us - Listed (OL)
UL-aplinkos temperatūra	-20 ... 60 °C
CE ženklas (žr. deklaraciją)	atitinka EU-EMV reikalvimus in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK RoHS instructions
Informacija	atitinka RoHS
Signalu nuotolis	0 - 20 mA +/-0,6 mA
Aplinkos temperatūra	-20 ... 70 °C
Jungiklio išėjimas	2xNPN
Perjungimo funkcija	Laisvai programuojamas
Komutavimo elemento funkcija	Perjungiamas
Atsparumas trumpam jungimui	Pulsuojantis
Perkrovimo galimybė	Galimas
Nominalus DC įtampos lygis	10 ... 30 V
Electrical connection 1, connection type	Kištuko lizdas
Electrical connection 1, connection technology	M8x1, A-coded to EN 61076-2-104
Electrical connection 1, number of pins/wires	4
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, connection type	Kištukas
Electrical connection 2, connection technology	M8x1, A-coded to EN 61076-2-104
Electrical connection 2, number of pins/wires	4
Electrical connection 2, type of mounting	Screw lock
Produkto svoris	19 g
Material housing	ABS
Nustatymo pasirinkimai	Teach-In
Apsaugos klasė	IP65
Atsparumo korozijai klasė CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L