
 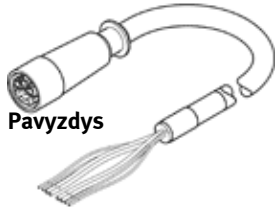


# Variklio kabelis NEBM-M23G8-E- -Q9N-LE8

Gaminio numeris: 550313  
Nebetiekiamas produktas

FESTO

For EMMS-AS-40/55 with resolver and EMMS-AS-70/100/140 with CMM-AS.



Pavyzdys

## Tech. Duomenys

| Savybės  | Reikšmė  |
|--|--|
| Atitinka standartus  | EN 61984   |
| Cable identification                                       | Without inscription label holder   |
| Electrical connection 1, function                          | Field device side  |
| Electrical connection 1, design                            | apvalus  |
| Electrical connection 1, connection type                   | Kištuko lizdas   |
| Electrical connection 1, cable outlet                      | Tiesus   |
| Electrical connection 1, connection technology             | M23x1  |
| Electrical connection 1, number of pins/wires              | 8  |
| Electrical connection 1, occupied pins/wires               | 8  |
| Electrical connection 2, function                          | Controller side  |
| Electrical connection 2, connection type                   | Kabelis  |
| Electrical connection 2, connection technology             | atviri laidai  |
| Electrical connection 2, number of pins/wires              | 8  |
| Electrical connection 2, occupied pins/wires               | 8  |
| Nominalus DC įtampos lygis                                 | 0 ... 630 V  |
| Note on operating voltage range DC                         | 0 - 300 V for 0.5 mm <sup>2</sup>  |
| Nominalus AC įtampos lygis                                 | 0 ... 630 V  |
| Note on operating voltage range AC                         | 0 - 300 V for 0.5 mm <sup>2</sup>  |
| Leistina srovės apkrova prie 40°C                          | 16 A   |
| Note on acceptable current load at 40°C                    | 8 A for 0.5 mm <sup>2</sup>  |
| Atsparumas smūgiams  | 4 kV   |
| Note on surge resistance                                   | 2.5 kV for 0.5 mm <sup>2</sup>   |
| Kabelio ilgis  | 1 ... 25 m   |
| Kabelio priedas  | tinkamas lanksčiai kabelio apsaugai  |
| Bending radius, fixed cable installation                   | ≥ 60 mm  |
| Bending radius, flexible cable installation                | ≥ 120 mm   |
| Kabelio skersmuo   | 12 mm  |
| Kabelio struktūra  | 4x1,5+2x(2x0,5)<br>Ekranuotas  |
| Nominalus laidininko skerspjūvis                           | 0,5 mm <sup>2</sup><br>1,5 mm <sup>2</sup>                                       |
| Laido galai  | Laido antgalis   |
| Apsaugos klasė   | IP65   |
| Note on degree of protection                               | Sumontuotas  |
| Aplinkos temperatūra                                       | -50 ... 90 °C  |
| Aplinkos temperatūra esant lanksčiai kabelių instaliacijai | -40 ... 90 °C  |
| CE ženklas (žr. deklaraciją)                               | atitinka EU reikalavimus žemose įtampose<br>in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity)               | To UK instructions for electrical equipment<br>To UK RoHS instructions           |
| PWIS conformity  | VDMA24364-B2-L   |
| Informacija  | atitinka RoHS  |
| Užterštumo laipsnis  | 3  |
| Material cable sheath                                      | TPE-U(PUR)   |
| Kabelio apvalkalo spalva                                   | oranžinis  |